

# Product Category

※ Red words are new products  
 ※ Please click on series names for related introduction webpages or specifications.

None PFC		With PFC	
	High Cost-Performance <u>LRS series</u> 35W~450/600W <u>LRS-N2 series</u> 100/200/350/600W <b>NEW</b>		Premium Industrial Power <u>HRP(G) series</u> 75~1000W <u>HRP(G)-N3 series</u> 150/300/600/1000W <b>NEW</b>
	Economic Mid-high Power <u>SE series</u> 450W~1500W	 	General Industrial Power <u>RSP series</u> 75W~3000W <u>NSP series</u> 1600/3200W <b>NEW</b> <u>SPV series</u> 150/300W(PV) <u>CSP series</u> 3000W(HV) <u>DPU series</u> 3200W <u>RST series</u> 5K/ 7K5(HV)/ 10K/ 15KW(HV) <u>SHP series</u> 10KW/30KW (HV) <b>NEW</b>
	Multi-channel (Single Vo) <u>RS series</u> 15W~150W (Dual Vo) <u>RD series</u> 35W~125W <u>RID series</u> 50W~125W (Triple Vo) <u>RT series</u> 50W~125W (Quad Vo) <u>RQ series</u> 50W~125W		Medical 2xMOPP/ MOOP Level <u>MSP series</u> 100W~1000W
	Security Power Supply (UPS) <u>LAD series</u> 120/240/360/600W		Conduction Power / Semi-potted <u>UHP series</u> 200W~1500(HV)/2500W, PHP-3500(HV)
			Harsh Environment / Fully Potted <u>HEP series</u> 100W~2300W(HV)

# Road Map Non-PFC

※ Red words are new products

Multiple Output

Multiple output, minimum load free  
 RS-15/ 25/ 35/ 50/ 75/ 100/ 150 series  
 RD-35/ 50/ 65/ 85/ 125 series  
 RID/ T/ Q-50/ 65/ 85/ 125 series



Economical Type

High cost-performance  
 LRS- 35/ 50/ 75/ 150/ 150F/ 200/ 350/ 450 /600 series


**NEW**

200% Peak Load  
 LRS-100N2/200N2/350N2/600N2 series



(350~600W with FAN cooling)

Economical medium-high power  
 SE-1000/ 1500 series

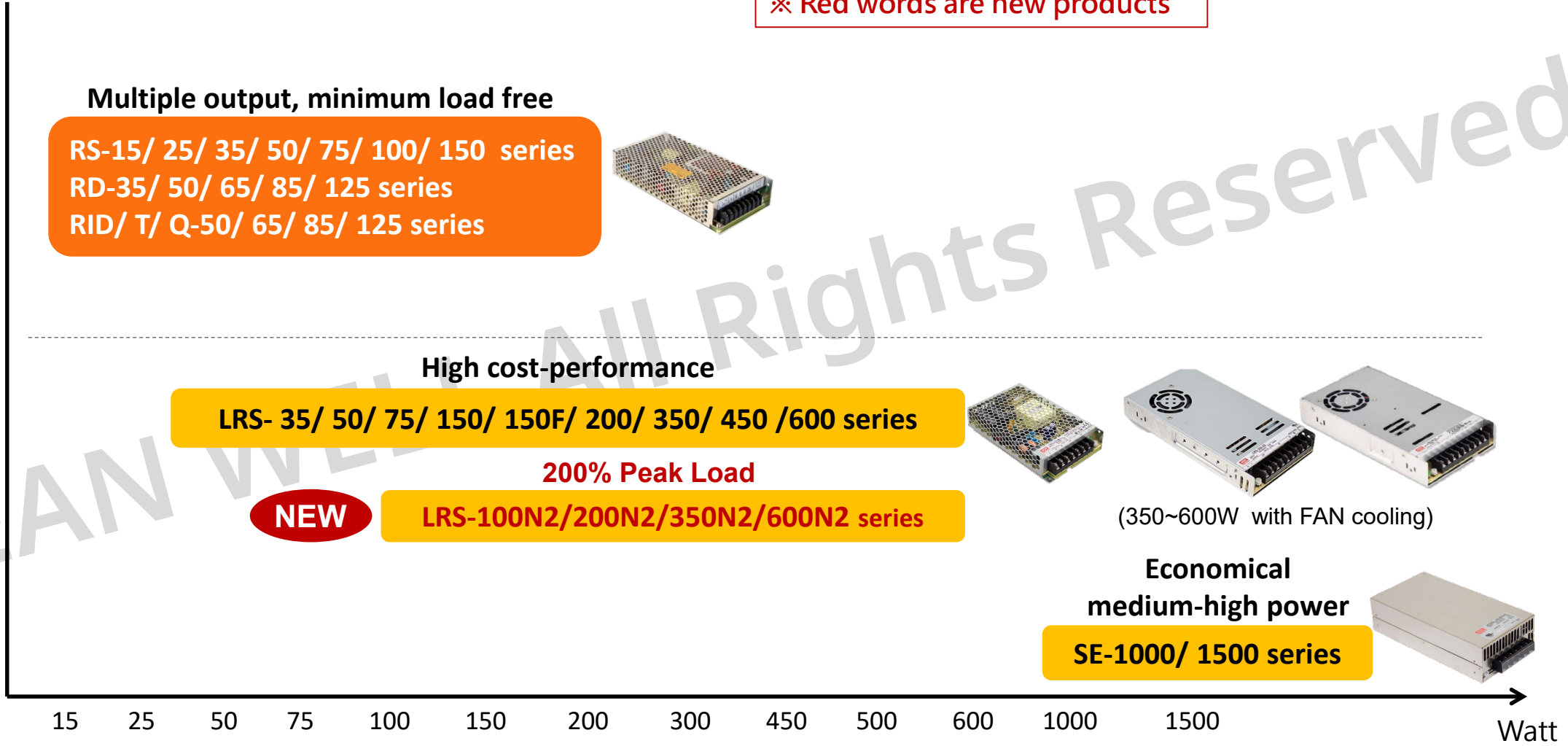

# Road Map PFC

※ Red words are new products

Premium

HRP(G)-75/ 100/ 150/ 200/ 300/ 450/ 600/ 1000 series



350% Peak Load

HRP(G)-150/300/600/1000N3 Series

**NEW**

General

>1000w with parallel function

RSP-75/100/150/200/240/320/500/750/1000/1500/1600/2000/2400/3000 series



**NEW**

NSP-1600/3200 series

Digital , 1U height

DPU-3200 series



**NEW**

3Ø AC input

RST-5K/7K5(HV)/10K/15K(HV), SHP-10K/30K-HV series

Programmable Output voltage



SPV-150/ 300 series

Square case



PSP(A)-600/ 1000 series

>120Vdc High output voltage



 
 
CSP-3000 series



Fanless

Conduction cooling, slim and low profile

UHP-200A/ 200/ 350/ 500/ 750/ 1000/ 1500/ 2500 series, PHP-3500(HV) series



# Road Map

## Specific Industrial PSU

Medical

2x MOPP/ 2x MOOP

MSP-100/ 200/ 300/ 450/ 600/ 1000 series



Security

Single/Dual output with battery charger (UPS)

AD/ ADS/ ADD-55/ 155 series



1U height design, Security/Fire alarm (UPS)

LAD-120/240/360/600 series



Harsh environment

Fully-potted, high IP rating

HEP- 100/ 150/ 185/ 240/ 320/ 480/ 600/ 1000/2300 series  
HEP-600C series



35 60 100 150 200 300 500 600 1000 2300 Watt