


Product Category

※ Red words are new products, and Blue words are under development products.
 ※ Please click on series names for related introduction webpages or specifications.

Economical Type		Built-in PFC	
	High Cost-Performance <u>LRS series</u> 35W~ 1200W NEW <u>LRS-N2 series</u> 100W/200W/350W/600W		Premium Industrial Power <u>HRP(G) series</u> 75W~1000W <u>HRP(G)-N3 series</u> 150W/300W/600W/1000W
	Economic Mid-high Power <u>SE series</u> 1000W / 1500W	 General Industrial Power <u>RSP series</u> 75W~3000W <u>NSP series</u> 75W~750W, 1000W/2400W COMING SOON 1600W/3200W <u>SPV series</u> 150W/300W <u>CSP series, DPU series</u> 3000W <u>RST series</u> 5KW/ 7.5KW/ 10KW/ 15KW <u>SHP series</u> 10KW/30KW	
	Multi-channels (Single Vo) <u>RS series</u> 15W~150W (Dual Vo) <u>RD series</u> 35W~125W <u>RID series</u> 50W~125W (Triple Vo) <u>RT series</u> 50W~125W (Quad Vo) <u>RQ series</u> 50W~125W		Medical 2xMOOPP/ MOOP Level <u>MSP series</u> 100W~1000W COMING SOON 1600W, 3200W
	Security Power Supply (UPS) <u>LAD series</u> 120W/240W/360W/600W		Conduction Power / Semi-potted <u>UHP series</u> 200W~2500W <u>PHP-3500(HV)</u>
			Harsh Environment / Fully Potted <u>HEP series</u> 100W~2300W

Roadmap

Economical

⊗ Red words are new products
 ⊗ For better cost-performance, we recommend using the LRS-1200 series to replace the SE-1000 series in new projects.


LRS-1200 series vs SE-1000 series Comparison Chart →

Multiple Output

Multiple output , minimum load free
 RS-15/ 25/ 35/ 50/ 75/ 100/ 150 series
 RD-35/ 50/ 65/ 85/ 125 series
 RID/ T/ Q-50/ 65/ 85/ 125 series



Low Profile

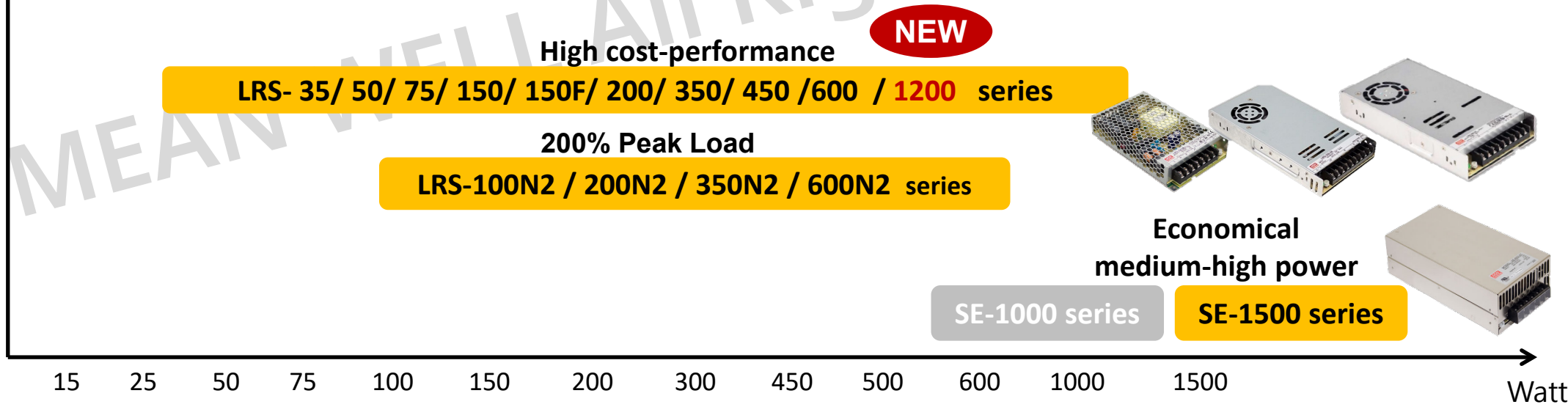

Roadmap PFC

※ Blue words are under development products.
 ※ For better cost-performance, we recommend using the NSP series to replace the RSP series in new projects.

NSP-75~2400 series vs RSP-75~2400 series Comparison Chart →

Premium

HRP(G)-75/ 100/ 150/ 200/ 300/ 450/ 600/ 1000 series

350% Peak Load HRP(G)-150/300/600/1000N3 Series



General

RSP-75/100/150/200/240/320/500/750/1000/1500/1600/2000/2400/3000 series

NEW NSP-75 / 100 / 150 / 200 / 240 / 320 / 500 / 750 / 1000 / 1600 / 2400 / 3200 series **COMING SOON**

Built-in PV/PC/ parallel / CANbus or MODbus optional · Slim and 1U height

DPU-3200 series



3Ø AC input

RST-5K / 7K5(HV) / 10K / 15K(HV) , SHP-10K/30K(HV) series

Programmable Output voltage

SPV-150/ 300 series



Square case

PSP(A)-600/ 1000 series



>120Vdc High Vo

 
CSP-3000 series



Fanless

Fanless design with conduction cooling, slim and low profile

UHP-200A/ 200/ 350/ 500/ 750/ 1000/ 1500/ 2500 series , PHP-3500(HV) series



Roadmap

Specific Industrial PSU

⊗ Blue words are under development products.

