

Rack Power & Charger Catalog

※ Please click on model name for specifications

Standalone Photo	Type	Model Name	Output Power	Output Voltage	Rackmount Photo	Model Name	Max. Output Power	Key Features
	PSU	<u>RCP-1000</u>	1kW	12/ 24/ 48V		<u>RCP-1U</u>	3kW	<ul style="list-style-type: none"> PV Function Hot Plug Support PMBus Parallel operation (Max. 8kW)
	PSU	<u>RCP-1600</u>	1.6kW	12/ 24/ 48V		<u>RHP-1U</u>	8kW	<ul style="list-style-type: none"> PV & PC PV Function Hot Plug Digital control, Support PMBus / CANbus Parallel operation(Max. 24kW) Built-in charging curves (Charger)
	Charger	<u>RCB-1600</u>	1.6kW	14.4/ 28.8/ 57.6V				
	PSU	<u>RCP-2000</u>	2kW	12/ 24/ 48V		<u>RKP-1U</u>	6kW	<ul style="list-style-type: none"> PV Function Hot Plug Support PMBus Parallel operation (Max. 18kW)
	PSU Charger	<u>NCP-3200</u>	3.2kW	24/48/ 380V		<u>DHP-1UT-B(HV)</u>	12.8kW	<ul style="list-style-type: none"> PV & PC PV Function Hot Plug Digital control Support PMBus / CANbus Parallel operation (Max. 128kW) PSU/Charger 2-in-1

Road Map Rack Power

※ Red words are new products

RCP-1000 Series 1kW

RCP-1U Max. 3kW



RCP-1600/ RCB-1600 Series 1.6kW

RHP-1U Max. 8kW



Digitalized



CANbus

RCP-2000 Series 2kW

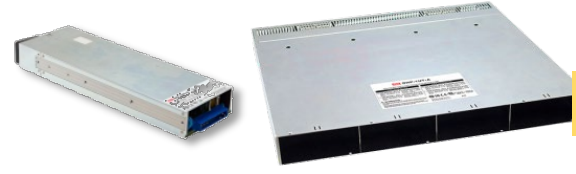
RKP-1U Max. 6kW



Fully Digitalized

NCP-3200 Series 3.2kW

DHP-1UT-B(HV) Max. 12.8kW


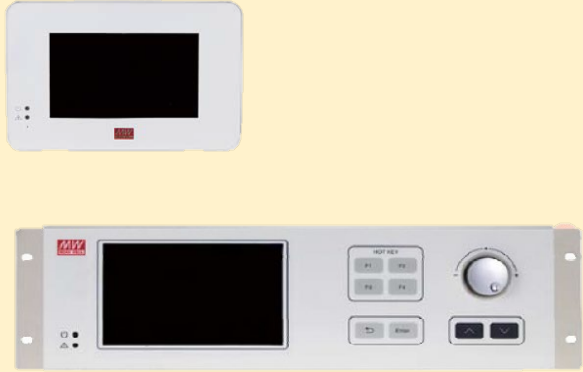


CANbus



Smart Controller Catalog

※ Please click on model name for specifications

Smart Controller	Picture	Corresponding Models	Key features
<p><u>CMU 1</u></p>		<p><u>RCP-1000/1000-C series</u></p>	<ul style="list-style-type: none"> ● 1U 19-inch rackmount and standalone ● Front panel LDC and web UI ● UES, RS-232 or ethernet interface for PC connection ● Alarm/event log with time and data ● Windows-based PC software ● 4 programmable relay outputs ● 5years warranty
		<p><u>RCP-1600 series</u> <u>RCB-1600 series</u></p>	
		<p><u>RCP-2000 series</u></p>	
<p><u>CMU 2</u></p>		<p><u>DRP-3200 series</u> <u>DBR-3200 series</u> <u>NCP-3200 series</u> NEW</p>	<ul style="list-style-type: none"> ● 3U 19-inch rackmount and standalone ● 7" TFT LCD touch panel and buttons ● Ethernet port for on-site and remote operation ● Selectable PMbus, CANbus, RS485, and RS-232 communication interface ● Power management/ Burn-in/EV charging/Horticulture firmware ready. ● Data/event log with time and date ● 4 programmable relay outputs ● 5 years warranty