










Rack Power & Charger Catalog

※ Please click on model name for specifications

Standalone Photo	Type	Model Name	Output Power	Output Voltage	Rackmount Photo	Model Name	Max. Output Power	Key Features
	PSU	RCP-1000	1kW	12/ 24/ 48V		RCP-1U	3kW	<ul style="list-style-type: none"> PV Function Hot Plug Support PMBus Parallel operation (Max. 8kW)
	PSU	RCP-1600	1.6kW	12/ 24/ 48V		RHP-1U	8kW	<ul style="list-style-type: none"> PV & PC PV Function Hot Plug Digital control, Support PMBus / CANbus Parallel operation(Max. 24kW) Built-in charging curves (Charger)
	Charger	RCB-1600	1.6kW	14.4/ 28.8/ 57.6V				
	PSU	RCP-2000	2kW	12/ 24/ 48V		RKP-1U	6kW	<ul style="list-style-type: none"> PV Function Hot Plug Support PMBus Parallel operation (Max. 18kW)
	PSU	DRP-3200	3.2kW	24/ 48V		DHP-1UT	12.8kW	<ul style="list-style-type: none"> PV & PC PV Function Hot Plug Digital control Support PMBus / CANbus Parallel operation (Max. 128kW) Built-in charging curves (Charger)
	Charger	DBR-3200	3.2kW	28.8/ 57.6V				




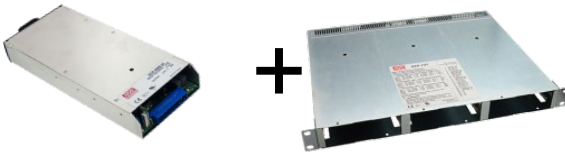
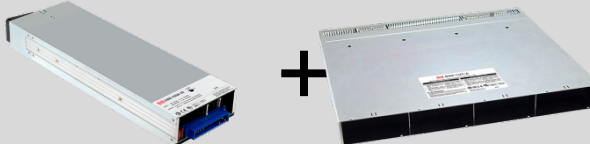
Rack Power & Charger Catalog

※ Please click on model name for specifications

Standalone Photo	Type	Model Name	Output Power	Output Voltage	Rackmount Photo	Model Name	Max. Output Power	Key Features
	PSU Charger	NEW <u>NCP-3200</u>	3.2kW	24/48/380V		<u>DHP-1UT-B(HV)</u>	12.8kW	<ul style="list-style-type: none"> • PV & PC PV Function • Hot Plug • Digital control • Support PMBus / CANbus • Parallel operation (Max. 128kW) • PSU/Charger 2-in-1

MEAN WELL ALL RIGHTS RESERVED

System Power Catalog

Rack Photo	Type	Output Voltage	Model No. (PSU included)	Max. Output Power	System Power Photo
	PSU	12/24/48V	RCP-3K1U	8kW	
	PSU	12/24/48V	RHP-8K1U	24kW	
	Charger	14.4/28.8/57.6V			
	PSU	12/24/48V	RKP-6K1U	18kW	
	PSU	24/48V	DHP-12K1U	128kW	
	Charger	28.8/57.6V			

Road Map Rack Power

※ Red words are new products

RCP-1000/1000-C Series **1kW**
RCP-1U **Max. 3kW**



RCP/RCB-1600 Series **1.6kW**
RHP-1U **Max. 8kW**



Digitalized



CANbus

RCP-2000 Series **2kW**
RKP-1U **Max. 6kW**




Fully Digitalized

DRP/DBR-3200 / **NCP-3200** Series **3.2kW**
DHP-1UT-A(B) **Max. 12.8kW**




CANbus

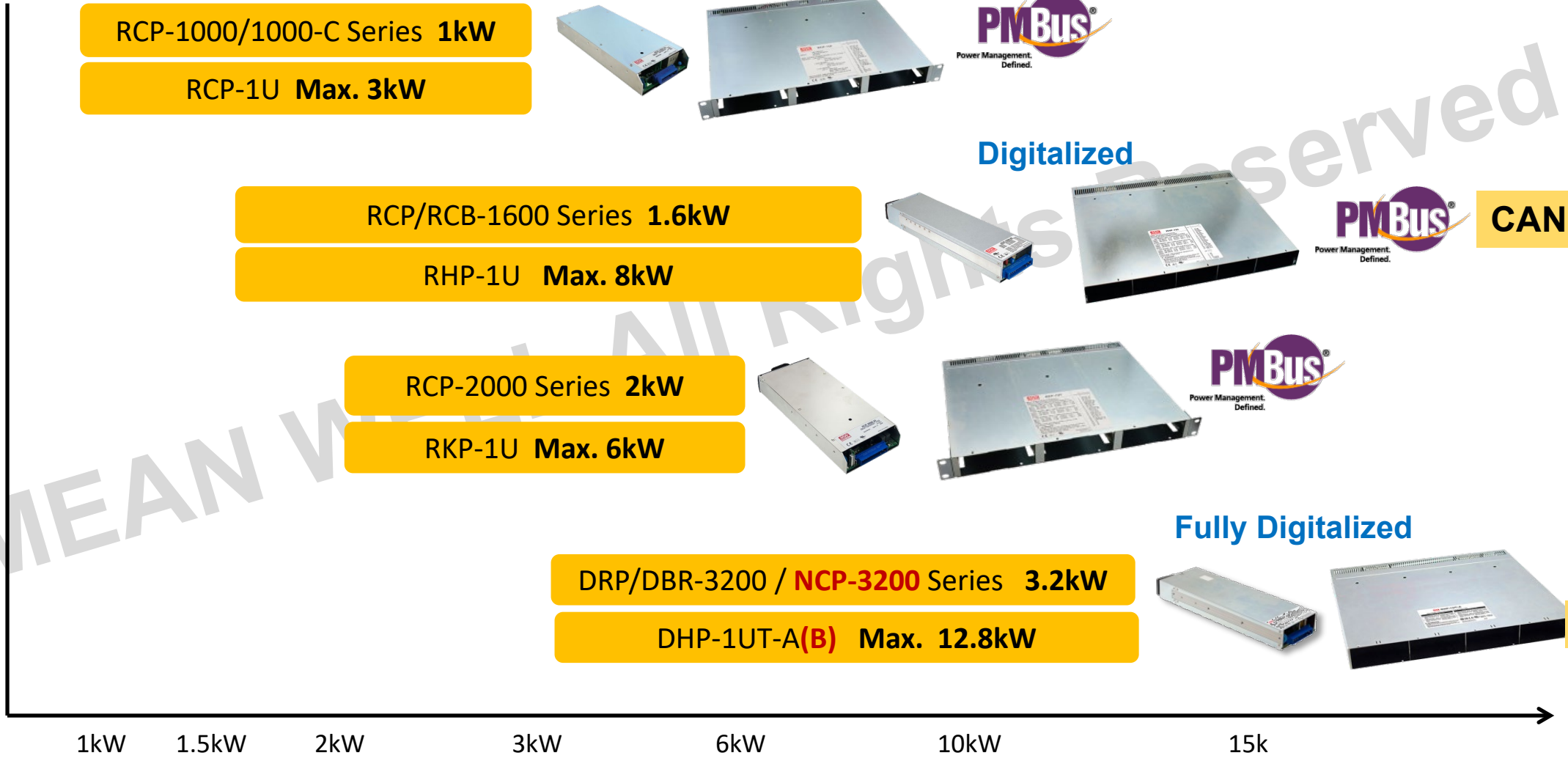


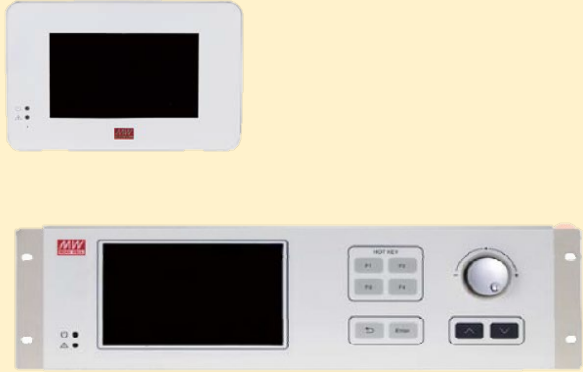
MEAN WELL All Rights Reserved

Road Map System Power

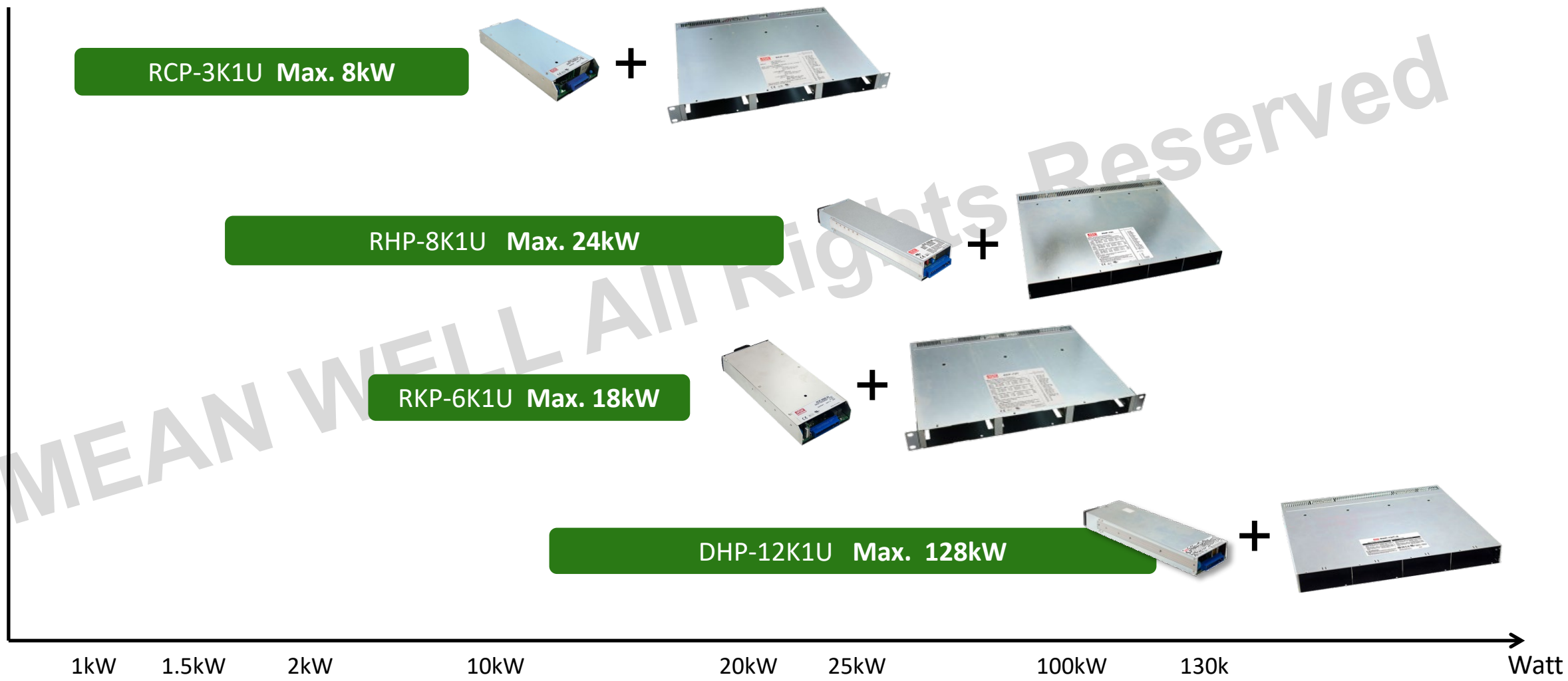

Smart Controller Catalog

※ Please click on model name for specifications

Smart Controller	Picture	Corresponding Models	Key features
<p><u>CMU 1</u></p>		<p><u>RCP-1000/1000-C series</u></p>	<ul style="list-style-type: none"> ● 1U 19-inch rackmount and standalone ● Front panel LDC and web UI ● UES, RS-232 or ethernet interface for PC connection ● Alarm/event log with time and data ● Windows-based PC software ● 4 programmable relay outputs ● 5years warranty
		<p><u>RCP-1600 series</u> <u>RCB-1600 series</u></p>	
		<p><u>RCP-2000 series</u></p>	
<p><u>CMU 2</u></p>		<p><u>DRP-3200 series</u> <u>DBR-3200 series</u> <u>NCP-3200 series</u> NEW</p>	<ul style="list-style-type: none"> ● 3U 19-inch rackmount and standalone ● 7" TFT LCD touch panel and buttons ● Ethernet port for on-site and remote operation ● Selectable PMbus, CANbus, RS485, and RS-232 communication interface ● Power management/ Burn-in/EV charging/Horticulture firmware ready. ● Data/event log with time and date ● 4 programmable relay outputs ● 5 years warranty